
 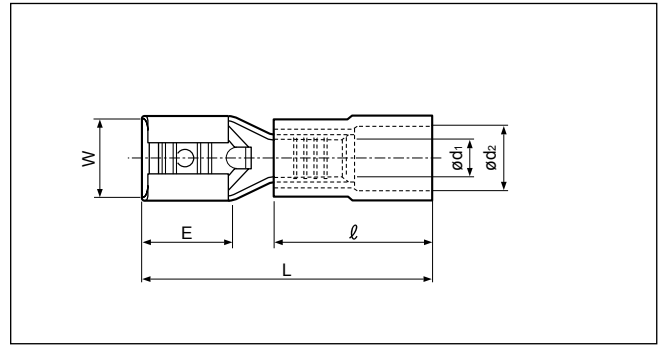


QUICK DISCONNECT Female



Vinyl-insulated with copper sleeve

Applicable Wire mm ²	Part No.	Nominal Size	Dimensions mm (in.)						Color	Tool No.	Qty/box
			W	L	E	ℓ	ø d ₁	ø d ₂			
0.5 to 1	VDADF1.25-110A-8	B2.8-1	3.2 (.126)	18.4 (.724)	6.4 (.252)	10.0 (.394)	2.1 (.083)	3.4 (.134)	Red	WC-2210DIN	1,000
	VDADF1.25-110A-5	A2.8-1	3.2 (.126)	18.4 (.724)	6.4 (.252)	10.0 (.394)	2.1 (.083)	3.4 (.134)	Red		1,000
	VDADF1.25-187A-8	4.8-1	5.0 (.197)	19.2 (.756)	6.0 (.236)	10.0 (.394)	1.9 (.075)	3.4 (.134)	Red		1,000
	VDADF1.25-187A-5		5.0 (.197)	19.2 (.756)	6.0 (.236)	10.0 (.394)	1.9 (.075)	3.4 (.134)	Red		1,000
>1 to 2.5	VDADF2-187A-8	4.8-2.5	5.0 (.197)	20.2 (.795)	6.0 (.236)	11.0 (.433)	2.5 (.098)	4.0 (.157)	Blue		1,000
	VDADF2-187A-5		5.0 (.197)	20.2 (.795)	6.0 (.236)	11.0 (.433)	2.5 (.098)	4.0 (.157)	Blue		1,000
	VDADF2-250A	6.3-2.5	6.6 (.260)	22.0 (.866)	7.8 (.307)	11.0 (.433)	2.4 (.094)	4.0 (.157)	Blue		1,000
>2.5 to 6	VDADF5.5-250A	6.3-6	6.6 (.260)	23.0 (.906)	7.8 (.307)	12.0 (.472)	3.7 (.146)	5.8 (.228)	Yellow	500	

Note: 1) Contact J.S.T.(U.K.) Ltd for the above tools.
 2) Reference: DIN46245 Contact J.S.T. DEUTSCHLAND GMBH for details.
 3) Delivery lead times may vary depending on the product. Contact JST for details.